




Pass and Seymour  
TradeMaster® 2-Gang Nylon Wall Plate, 2 Decorator Openings, Gray  
Part No. TP262GRYCC12

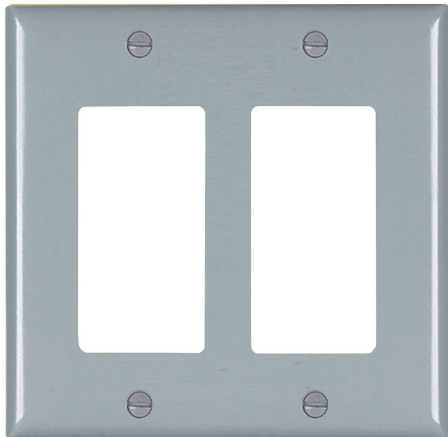

The TradeMaster® thermoplastic 2-gang decorator wall plate provides maximum durability in plastic wall plates. Self-extinguishing nylon construction makes these wall plates virtually unbreakable. They are 3/16 of an inch higher and wider than typical plastic wall plates - not enough to be apparent to the eye, but the extra size cuts cost by reducing dry wall rework.

## Features & Benefits

Molded of rugged, practically indestructible self-extinguishing nylon. ('TP' series only)

Available in 'TP' series, extra 3/16 inch width and height than Standard size plates: and 'TPJ' series, extra 3/16 inch width and height than Junior-Jumbo size plates

Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond

Preferred for hospital, industrial, institutional, and other high-abuse applications

Nominal thickness, .070 inch

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Gray
Finish	Matte	UPC Number	785007855852
Country Of Origin	Mexico	Construction	Plastic
Wall Plate Size	Standard Size	Wall Plate Type	Decorator
Application Sector	Commercial, Residential	Warranty Type	1-Year Limited Warranty
Type	Wall Plate		

### Dimensions

Product Width US	4.75 in	Product Depth US	0.065 in
------------------	---------	------------------	----------

Product Height US	4.69 in
-------------------	---------

Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

Additional Information

Product Environmental Profile	Yes
-------------------------------	-----

Technical Information

Thickness	0.065 in	Number of Gangs	2
-----------	----------	-----------------	---

Indoor/Outdoor	Indoor	Mounting Type	Box Mounted
----------------	--------	---------------	-------------

Orientation	Vertical
-------------	----------