




Pass and Seymour  
Decorator Openings, Three Gang, Ivory  
Part No. TP263I

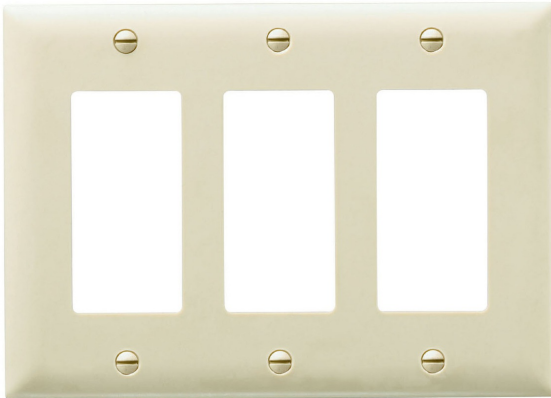

The TradeMaster® thermoplastic 3-gang decorator wall plate provides maximum durability in plastic wall plates. Self-extinguishing nylon construction makes these wall plates virtually unbreakable. They are 3/16 of an inch higher and wider than typical plastic wall plates - not enough to be apparent to the eye, but the extra size cuts cost by reducing dry wall rework.

## Features & Benefits

Molded of rugged, practically indestructible self-extinguishing nylon. ('TP' series only.)

Available in 'TP' series, extra 3/16 inch width and height than Standard size plates: and 'TPJ' series, extra 3/16 inch width and height than Junior-Jumbo size plates.

Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

Preferred for hospital, industrial, institutional, and other high-abuse applications.

Nominal thickness, .070 inch.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Ivory
Country Of Origin	United States	Wall Plate Type	Dimmer/Switch, Outlet
Application Sector	Residential/Commercial	Standard	CSA, UL514

### Dimensions

Product Width US	6.563 in	Product Depth US	0.25 in
Product Height US	4.6875 in		

### Listing Agencies / 3rd Party Agencies

cULus ListingNumber	143222	cULus Listed	Yes
---------------------	--------	--------------	-----

---

## Additional Information

---

Product Environmental Profile Yes

---

## Technical Information

---

Cutout	Decorator	Thickness	0.07 in
Number of Gangs	3	Mounting Type	Exposed Screws

---