




Pass and Seymour  
TradeMaster® 3-Gang Nylon Wall Plate, 2 Toggle Switch Openings, 1 Duplex Receptacle Opening, White  
Part No. TP28W

Trademaster Plate 3-Gang, 2-toggle, 1-duplex receptacle

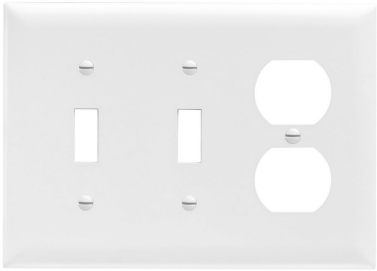

Features & Benefits

- Molded of rugged, practically indestructible self-extinguishing nylon.  
['TP' series only.]
- High Impact resistant nylon face.
- Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.
- Preferred for hospital, industrial, institutional, and other high-abuse applications.
- Nominal thickness, .070 inch.

Specifications

General Info			
Product Line	Pass & Seymour	Color	White
Finish	Matte	UPC Number	785007275186
Country Of Origin	Mexico	Construction	Plastic
Wall Plate Size	Standard Size	Wall Plate Type	Combination, Duplex Receptacle, Toggle Switch
Application Sector	Commercial, Residential	Standard	CSA, UL514
Warranty Type	1-Year Limited Warranty	Type	Wall Plate
Dimensions			
Product Width US	6.563 in	Product Depth US	0.25 in
Product Height US	4.6875 in		
Listing Agencies / 3rd Party Agencies			
cULus ListingNumber	143222	cULus Listed	Yes

Additional Information

Product Environmental Profile	Yes
-------------------------------	-----

Technical Information

Thickness	0.07 in	Number of Gangs	3
-----------	---------	-----------------	---

Indoor/Outdoor	Indoor	Mounting Type	Box Mounted
----------------	--------	---------------	-------------

Orientation	Vertical
-------------	----------