




Pass and Seymour
TradeMaster® 4-Gang Nylon Wall Plate, 4 Toggle Switch Openings, Black
Part No. TP4BK

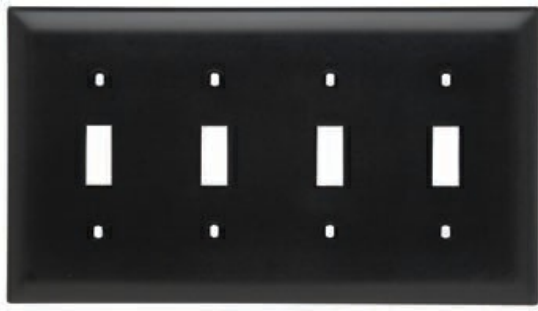

Trademaster Plate 4-Gang 4toggle

Features & Benefits

Molded of rugged, practically indestructible Available in 'TP' series, extra 3/16 inch width and height than Standard size plates: self-extinguishing nylon. ('TP' series only.) and 'TPJ' series, extra 3/16 inch width and height than Junior-Jumbo size plates.

Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

Preferred for hospital, industrial, institutional, and other high-abuse applications.

Nominal thickness, .070 inch.

For covering patents, see www.legrand.us/patents.

Specifications

General Info

| | | | |
|--------------------|-------------------------|-----------------|---------------|
| Product Line | Pass & Seymour | Color | Black |
| Finish | Matte | UPC Number | 785007274226 |
| Country Of Origin | Mexico | Construction | Plastic |
| Wall Plate Size | Standard Size | Wall Plate Type | Toggle Switch |
| Application Sector | Commercial, Residential | Standard | CSA, UL514 |
| Warranty Type | 1-Year Limited Warranty | Type | Wall Plate |

Dimensions

| | | | |
|-------------------|-----------|------------------|---------|
| Product Width US | 8.375 in | Product Depth US | 0.25 in |
| Product Height US | 4.6875 in | | |

Listing Agencies / 3rd Party Agencies

| | | | |
|---------------------|--------|--------------|-----|
| cULus ListingNumber | 143222 | cULus Listed | Yes |
|---------------------|--------|--------------|-----|

Additional Information

| | |
|-------------------------------|-----|
| Product Environmental Profile | Yes |
|-------------------------------|-----|

Technical Information

| | | | |
|----------------|----------|-----------------|---------------|
| Thickness | 0.07 in | Number of Gangs | 4 |
| Indoor/Outdoor | Indoor | Mounting Type | Strap Mounted |
| Orientation | Vertical | | |
