




Pass and Seymour  
TradeMaster® 2-Gang Nylon Wall Plate, 2 Duplex Receptacle Openings, Brown  
Part No. TP82

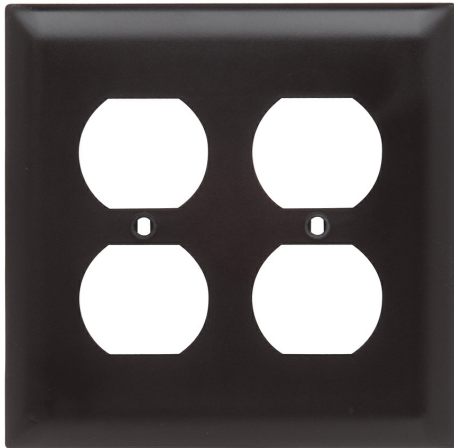

Trademaster Plate,double gang and duplex plate, is molded of rugged, practically indestructible self-extinguishing nylon. It is preferred for hospital, industrial, institutional, and other high-abuse applications. Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

## Features & Benefits

Molded of rugged, practically indestructibleAvailable in 'TP' series, extra 3/16 inch width and height than Standard size plates: self-extinguishing nylon. ('TP' series only.) and 'TPJ' series, extra 3/16 inch width and height than Junior-Jumbo size plates.

Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

Preferred for hospital, industrial, institutional, and other high-abuse applications.

Nominal thickness, .070 inch.

For covering patents, see [www.legrand.us/patents](http://www.legrand.us/patents).

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Brown
Finish	Matte	UPC Number	785007275193
Country Of Origin	United States	Construction	Plastic
Wall Plate Size	Standard Size	Wall Plate Type	Duplex Receptacle
Application Sector	Commercial, Residential	Standard	CSA, UL514
Warranty Type	1-Year Limited Warranty	Type	Wall Plate

### Dimensions

Product Width US	4.75 in	Product Depth US	0.25 in
Product Height US	4.6875 in		

---

### Listing Agencies / 3rd Party Agencies

---

cULus ListingNumber	143222	cULus Listed	Yes
---------------------	--------	--------------	-----

---

### Additional Information

---

Product Environmental Profile	Yes
-------------------------------	-----

---

### Technical Information

---

Thickness	0.07 in	Number of Gangs	2
Indoor/Outdoor	Indoor	Mounting Type	Strap Mounted
Orientation	Vertical		

---