




Pass and Seymour
Duplex Receptacle Openings, One Gang, White
Part No. TP8W

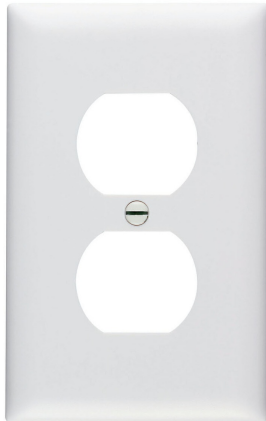

Trademaster, single gang, duplex wall plate molded of rugged, practically indestructible self-extinguishing nylon. It is preferred for hospital, industrial, institutional, and other high-abuse applications. Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

Features & Benefits

Molded of rugged, practically indestructible self-extinguishing nylon. ('TP' series only.)

Available in 'TP' series, extra 3/16 inch width and height than Standard size plates: and 'TPJ' series, extra 3/16 inch width and height than Junior-Jumbo size plates.

Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

Preferred for hospital, industrial, institutional, and other high-abuse applications.

Nominal thickness, .070 inch.

For covering patents, see www.legrand.us/patents.

Specifications

General Info

| | | | |
|--------------------|------------------------|-----------------|------------|
| Product Line | Pass & Seymour | Color | White |
| Country Of Origin | United States | Wall Plate Type | Outlet |
| Application Sector | Residential/Commercial | Standard | CSA, UL514 |

Dimensions

| | | | |
|-------------------|-----------|------------------|---------|
| Product Width US | 2.9375 in | Product Depth US | 0.25 in |
| Product Height US | 4.6875 in | | |

Listing Agencies / 3rd Party Agencies

| | | | |
|---------------------|--------|--------------|-----|
| cULus ListingNumber | 143222 | cULus Listed | Yes |
|---------------------|--------|--------------|-----|

Additional Information

Product Environmental Profile Yes

Technical Information

| | | | |
|-----------------|------------|---------------|----------------|
| Cutout | Receptacle | Thickness | 0.07 in |
| Number of Gangs | 1 | Mounting Type | Exposed Screws |
