




**Pass and Seymour**  
**Duplex Receptacle Openings, One Gang, Light Almond**  
Part No. TPJ8LA

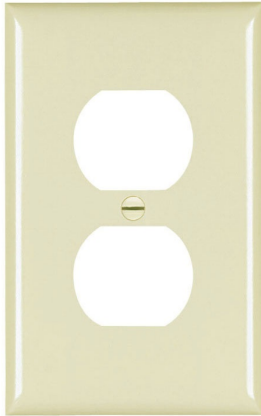

Trademaster, single gang, duplex, jumbowall plate in white is molded of rugged, practically indestructible self-extinguishing nylon. It is preferred for hospital, industrial, institutional, and other high-abuse applications. Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

## Features & Benefits

Molded of rugged, practically indestructible self-extinguishing nylon. ('TP' series only.)

Available in 'TP' series, extra 3/16 inch width and height than Standard size plates: and 'TPJ' series, extra 3/16 inch width and height than Junior-Jumbo size plates.

Available in Ivory, White, Brown, Gray, Black, Blue, Orange, Red, and Light Almond.

Preferred for hospital, industrial, institutional, and other high-abuse applications.

Nominal thickness, .070 inch.

For covering patents, see [www.legrand.us/patents](http://www.legrand.us/patents).

## Specifications

### General Info

|                    |                        |                   |               |
|--------------------|------------------------|-------------------|---------------|
| Product Line       | Pass & Seymour         | Country Of Origin | United States |
| Application Sector | Residential/Commercial | Standard          | CSA, UL514    |

### Dimensions

|                   |           |                  |         |
|-------------------|-----------|------------------|---------|
| Product Width US  | 3.3125 in | Product Depth US | 0.25 in |
| Product Height US | 5.0625 in |                  |         |

### Listing Agencies / 3rd Party Agencies

|                     |        |              |     |
|---------------------|--------|--------------|-----|
| cULus ListingNumber | 143222 | cULus Listed | Yes |
|---------------------|--------|--------------|-----|

### Additional Information

---

Product Environmental Profile    Yes

---

### Technical Information

---

|        |            |           |         |
|--------|------------|-----------|---------|
| Cutout | Receptacle | Thickness | 0.07 in |
|--------|------------|-----------|---------|

---

|                 |   |
|-----------------|---|
| Number of Gangs | 1 |
|-----------------|---|

---