




Pass and Seymour  
15A 125V Tamper-Resistant Duplex Receptacle with USB A/C Charging Ports, Light Almond  
Part No. TR15USBACLA

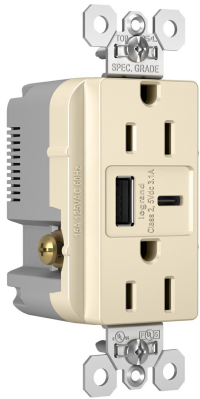

Combination Tamper-Resistant 15A Duplex Convenience Receptacles with two 3.1A USB charging ports Type A and C

## Features & Benefits

Protects children: patented shutter system helps prevent improper insertion of foreign objects

Meets National Electrical Code® Tamper-Resistant requirement

Conducts an automatic test every three seconds, ensuring it's always ready to protect. If the device fails the test, the indicator light flashes to signal that the GFCI should be replaced. It also has our proven SafeLock® Protection feature: if critical components are damaged and protection is lost, power to the receptacle is disconnected

High-impact-resistant thermoplastic construction with tri-drive terminal screws

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Light Almond
Country Of Origin	China	Number of Receptacles	2
Features	USB-A Charging, USB-C Charging	Outlet Type	Commercial, Indoor, Residential, Tamper-Resistant, USB-Charging
Type	Outlet		

### Dimensions

Product Width US	1.693 in	Product Depth US	1.425 in
Product Height US	2.677 in		

### Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

### Additional Information

Product Environmental Profile	Yes
-------------------------------	-----

---

## Technical Information

---

USB Amperage	3.1 A	Number of USBs	2
--------------	-------	----------------	---

---

USB Power Output	15 W	Amperage	15 A
------------------	------	----------	------

---

Number of Poles	Double Pole	Indoor/Outdoor	Indoor
-----------------	-------------	----------------	--------

---

Voltage	125.0 V
---------	---------

---