




radiant Collection  
radiant® 20A Tamper Resistant Ultra Fast PLUS Power Delivery USB Type C/C Outlet, Gray  
Part No. TR20USBPDRY

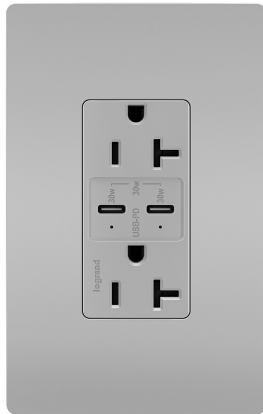

20A Tamper-Resistant Ultra Fast PLUS Power Delivery USB Type CC Outlet Made exclusively for use with screwless Wall Plates from the radiant® Collection, sold separately.

## Features & Benefits

- Charge the latest devices up to 2X as fast, thanks to the industry-leading 6.0A of our Ultra-Fast line and a whopping 30W of power courtesy of advanced Power Delivery
  - Built for intelligent charging, the outlet detects and delivers the precise amount of power needed to maximize charging speeds
- Provides fast and convenient built-in charging through two future-proof USB Type-C ports, accommodating new and upcoming devices without an adapter
  - Helpful indicator light lets you see charging status at a glance. Light glows yellow while charging is in progress, and shows green once the device battery is sufficiently charged
- Includes multiple layers of overcurrent protection, ensuring the outlet and your favorite devices can charge at optimal levels without risk of damage
  - All Legrand USB Outlets are manufactured through high-quality design, sourcing and production, and backed by a Lifetime Warranty
- Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisi-shutters" for an invisible effect
  - Replaces a traditional outlet easily, in as little as 10 minutes, with features like scalloped cover design and posted side-wire terminal screws for faster installation
- More color options available to fit any style, including finishes to match current hardware and lighting trends

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Gray
Finish	Matte	Country Of Origin	China
Features	USB-C Charging	Outlet Type	USB-Charging
Application Sector	Commercial	Type	Tamper-Resistant, USB

### Dimensions

Product Width US	1.69 in	Product Depth US	1.42 in
------------------	---------	------------------	---------

---

Product Height US	2.63 in
-------------------	---------

---

#### Additional Information

---

RoHS Conformant	Yes
-----------------	-----

---

#### Technical Information

---

USB Amperage	6 A	Connection	USB Type C/C
--------------	-----	------------	--------------

---

Number of USBs	2	USB Power Output	30 W
----------------	---	------------------	------

---

Amperage	20 A	Current Rating	20 A
----------	------	----------------	------

---

Indoor/Outdoor	Indoor	Mounting Type	Box
----------------	--------	---------------	-----

---

Voltage	125.0 V
---------	---------

---