




Pass and Seymour
Hard-Use Spec Grade Plug Load Controllable Receptacle, 20A, 125V, Gray
Part No. TR5362CDGRY

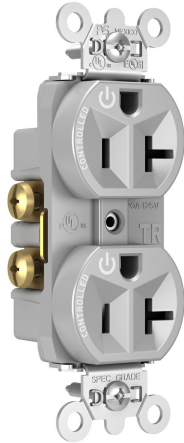

Permanent controlled receptacle marking allows for long-lasting, easy identification of controlled receptacle for end-users. NEMA-approved and compliant with NEC, CA Title 24, and ASHRAE Energy Efficiency Standard 90.1.

Features & Benefits

- Can be wired to any number of system-based or stand-alone plug load control solutions.
 - Corrosion-resistant, plated and tabbed steel strap locked in to face and back body to resist pulling away from face/body assembly.
- .032 inch thick, brass, triple-wipe power contacts for lasting retention.
 - Permanent controlled receptacle markings using abrasion resistant ink.
- Two drive screws anchor strap to back body and face where abrupt removal torque is strongest.
 - Tri-drive brass-plated terminal screws. Two back-wire holes for more wiring flexibility.
- Dual mechanical shutter system to help prevent insertion of foreign objects (for Tamper-Resistant models).
 - Strap tabs wrap around face to prevent strap from separating from face and back body.
- CH Version Only: Split circuit tab broken at the factory, allowing half of the receptacle to be controlled.
 - For covering patents, see www.legrand.us/patents.
- For compatible wall plate options, from our TradeMaster unbreakable plates to our radiant screwless plates to our metal wall plates, [click here](#).

Specifications

General Info

Product Line	Pass & Seymour	Color	Gray
Country Of Origin	Mexico		

Dimensions

Product Width US	1.322 in	Product Depth US	0.78 in
------------------	----------	------------------	---------

Product Height US 2.635 in

Listing Agencies / 3rd Party Agencies

cULus ListingNumber 140596 cULus Listed Yes

Technical Information

Amperage 20 A
