




Wiremold
4047 Two-Gang Cover Single Rectangular Opening
Part No. V4047RX

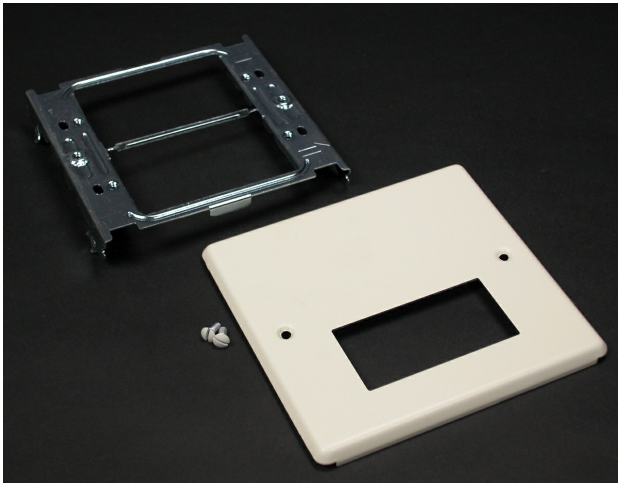

Accepts rectangular GFCI, Surge and Decorator style devices. Does not accept 5507 Series Faceplates. NOTE: Certified to Canadian Safety Standards for sale in Canada. When ordering these products, change the "V" color prefix to "CV" or the "G" color prefix to "CG" to denote the Canadian versions.

Features & Benefits

Accepts rectangular GFCI, Surge and Decorator style devices

Does not accept 5507 Series Faceplates

NOTE: Certified to Canadian Safety Standards for sale in Canada

When ordering these products, change the "V" color prefix to "CV" or the "G" color prefix to "CG" to denote the Canadian versions

Specifications

General Info

| | | | |
|--------------------|-------------------------|-------------------|---|
| Product Line | Wiremold | Color | Ivory |
| UPC Number | 786776050875 | Country Of Origin | United States |
| Application Sector | Commercial, Residential | Standard | cULus Listed Raceway: File E4376 Guide RJBT. Fittings: File E41751 Guide RJPR. Base & Blank Cover: Meets Article 386 of NEC. Meets Section 12-600 of CEC. |
| Type | Raceway | | |

Dimensions

| | | | |
|-------------------|----------|-------------------|---------|
| Product Width US | 4.75 in | Product Weight US | 0.38 lb |
| Product Length US | 5.125 in | | |

Trade Programs

| | |
|-------|-----|
| USMCA | Yes |
|-------|-----|

Additional Information

| | | | |
|----------------|-----|-------------------------------|-----|
| RoHS Compliant | Yes | Product Environmental Profile | Yes |
|----------------|-----|-------------------------------|-----|

Technical Information

| | |
|---------|---------|
| Voltage | 600.0 V |
|---------|---------|
