




Vantage  
Standard Dimming Module 12 Load Retro Terminal Kit + Plastic Back Plate  
Part No. TROSDM12-P-KIT

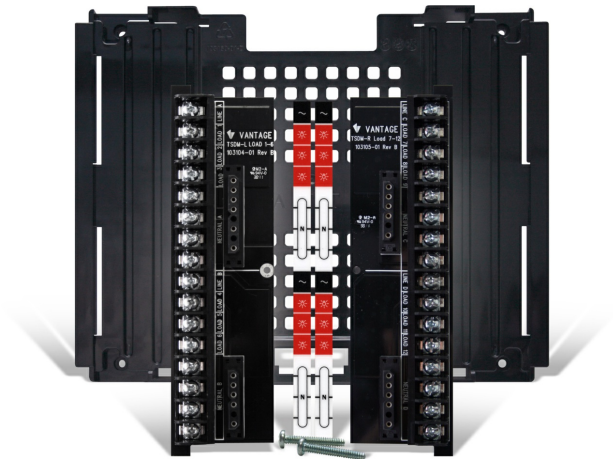

Vantage's AC Terminal Boards are sold and installed separately from the enclosures. This allows the installer to use different module models inside the enclosure. The TROSDM12-P-KIT supports the SDM12-EM Module for retrofit installations in existing enclosures.

## Features & Benefits

Terminal boards support 12 loads as well as two line feeds and 16 neutrals.

Includes one TSDM-L (6 load, left board), one TSDM-R (6 load, right board), module load labels (one pair), two #6-32 x 7/8 Screws, one plastic back plate

For enclosures with plastic standoffs (enclosures shipped after February 2005) instead of pem-studs (metal standoffs), the new plastic back plate is needed.

## Specifications

### General Info

Product Line	Vantage	UPC Number	804428066965
Country Of Origin	China	Application Sector	Commercial, Residential
Warranty Type	5-Year	Type	Terminal Board

### Dimensions

Product Width US	2.125 in	Product Weight US	10.4 oz
Product Depth US	0.875 in	Product Height US	7.8 in

### Listing Agencies / 3rd Party Agencies

cUL Listed	Yes
------------	-----

### Additional Information

---

Energy Savings                      No

---

**Technical Information**

---

Compatibility                      InFusion                                      Wire Gauge                      10-14 AWG

---

Storage Humidity                      5-95% RH (Non-Condensing)                      Indoor/Outdoor                      Indoor

---

Operating Temperature                      0°-40°C, 32°-104°F

---