




Ortronics
Clarity 6 VoIP Modular Patch Cord, 15', white
Part No. VC615-09

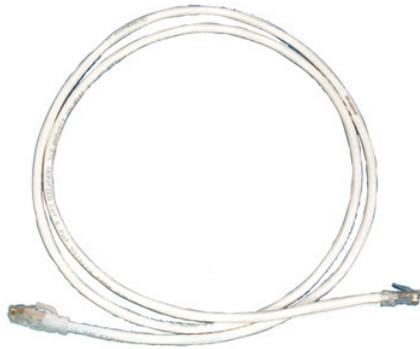

Clarity 6 Modular VoIP Patch Cord, white, 15', Category 6, four-pair UTP stranded 24 AWG PVC/CM, center tuned with Clarity 6 connecting hardware for optimum Category 6 installed performance using Ortronics Paralign 2 pair positioning technology. The VoIP cords provide an extra low-profile Clarity plug at one end to address cable bend requirements when plugging into the bottom of an IP phone set. The other cord end offers the full protective attributes of the Paralign 2 plug.

Features & Benefits

Works well with VoIP phones that have limited bend radius under phone

Specifications

General Info

Product Line	Ortronics	Color	White
UPC Number	662875514961	Country Of Origin	Mexico
Features	Standard Diameter	Application Sector	Commercial, Industrial
Standard	ANSI/TIA-568.E-2;ISO/IEC 11801-1;RoHS	Warranty Type	5-Year
Type	Copper Patch Cord		

Dimensions

Product Length US	15.0 FT	Cable Length	15 ft
-------------------	---------	--------------	-------

Additional Information

RoHS Compliant	Yes
----------------	-----

Technical Information

Operating Temperature Min	-10 °C	Category Performance Application	Cat6
Compatibility	RJ-45	Wire Gauge	24 AWG
Storage Humidity	0-90% RH (Non-Condensing)	Plating Specification	50 μ in Gold
Jacket Application	Riser Rated	Bend Radius	0.88 in
Shielded/Unshielded Cable	Unshielded	Termination Style	Pre-Terminated
Conductor Stranding	Stranded	Operating Temperature Max	60 °C
Cable Type	Non-Booted	Jacket Rating	CM Rated
Cable Diameter	0.22 in	Braid	Non-braided Wiring
Connector 2	RJ-45 Male	Connector 1	RJ-45 Male
Operating Temperature	-10°-60°C	Operating Humidity	0-90% RH (Non-Condensing)
Conductor Material	Copper	Voltage	300.0 V
Storage Temperature	-40° - 60° C		