




**Wattstopper**  
**Wattstopper PLUS 5.7", Graphic Switch Touchscreen with PoE, Black**  
Part No. EN-GS-150-BK

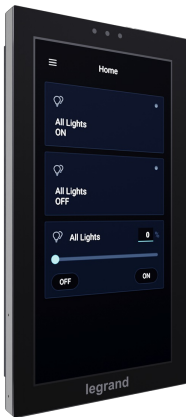

The EN-GS-150 graphic switch is a native Wattstopper PLUS PoE powered wired device with a 5.7" capacitive touch LCD display that enables simple control for complex spaces. The user interface provides an intuitive professional experience for whole room control of lights, shades, scenes, and tunable white loads. The EN-GS-150 is fully programmable with Polaris Config software enabling facility managers to customize button text, icons, and sequence of operations.

## Features & Benefits

Full color capacitive touch LCD display with native Wattstopper PLUS support

Control support for lights, shades, scenes, tunable white, and network groups

Attractive streamlined aesthetic with full glass face, available in Black or White with aluminum trim

Intuitive user interface supports up to 8 screens and multiple button types per screen

System-wide zone control within the Wattstopper PLUS system

Compatible with Wattstopper PLUS GreenBus, Wireless, and DALI managers

Power-over-Ethernet (PoE) connectivity for streamlined installation

## Specifications

### General Info

Product Line	Wattstopper	Color	Black
Finish	Gloss	Country Of Origin	China
Material	Glass	Product Series	EN-GS
Switch Type	Touch	Number of Switches	0
Application Sector	Commercial	Standard	CE, FCC, RoHS, IEEE 802.3af, IEEE 802.3at, UL, cUL
Warranty Type	5-Year	Type	User Interface

### Dimensions

---

Product Width US	2.6 in	Product Weight US	0.6 lb
------------------	--------	-------------------	--------

---

Product Depth US	1.24 in	Product Height US	5.9 in
------------------	---------	-------------------	--------

---

### Listing Agencies / 3rd Party Agencies

---

CE Certified	Yes	FCC Compliant	Yes
--------------	-----	---------------	-----

---

cUL Listed	Yes		
------------	-----	--	--

---

### Additional Information

---

RoHS Compliant	Yes	Energy Savings	No
----------------	-----	----------------	----

---

### Technical Information

---

Operating Temperature Min	32 °F	Compatibility	Wattstopper PLUS Wired, Wattstopper PLUS Wireless
---------------------------	-------	---------------	--

---

Has Battery	No	Number of Connections	1
-------------	----	-----------------------	---

---

Power Supply	PoE	Operating Temperature Max	122 °F
--------------	-----	---------------------------	--------

---

Number of Buttons	0	Number of Rockers	0
-------------------	---	-------------------	---

---

Power Consumption	4 W	Topology	Star
-------------------	-----	----------	------

---

Input Voltage	48 VDC	Indoor/Outdoor	Indoor
---------------	--------	----------------	--------

---

Mounting Type	Wall	Operating Temperature	32°-122°F
---------------	------	-----------------------	-----------

---

Operating Humidity	5-85% RH (Non-Condensing)	Location Rating	Dry
--------------------	---------------------------	-----------------	-----

---

Wire Connection Type	RJ-45	Storage Temperature	-4° - 140° F
----------------------	-------	---------------------	--------------

---