




Wiremold  
WMFB2KS8B Series Dual-Gang Floor Box Assembly  
Part No. WMFB2KS8B

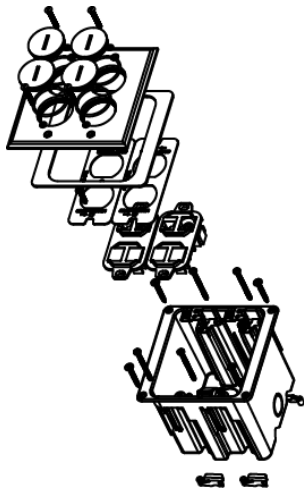

Includes dual-gang box, two 106 adapter with eight openings for communication devices, and brass cover with four screw plugs. For hole cut dimensions, see installation instructions sheet. Box Dimensions: 3 1/4" W x 3 3/4" L x 3 7/8" D (83mm W x 95mm L x 98mm D) Device Plate: 4 7/8" W x 5 1/16" L (124mm W x 129mm L).

## Features & Benefits

Includes dual-gang box, two 106 adapter with eight openings for communication devices, and brass cover with four screw plugs. Box Dimensions: 3 1/4" W x 3 3/4" L x 3 7/8" D (83mm W x 95mm L x 98mm D) Device Plate: 4 7/8" W x 5 1/16" L (124mm W x 129mm L).

For hole cut dimensions, see installation instructions sheet.

## Specifications

### General Info

Product Line	Wiremold	UPC Number	786564054047
Country Of Origin	China	Construction	Not Assembled
Cover Style	Surface	Cover Material	Brass
Application Sector	Commercial, Residential	Standard	cULus Listed Nonmetallic Outlet Boxes: File E143222 Guide QCMZ. Meets Article 314.27(C) of NEC.
Warranty Type	1-Year from Installation or 2-Years from Day of Sale	Type	Floor Box

### Dimensions

Product Width US	3.25 in	Product Weight US	1.64 lb
Product Depth US	3.875 in	Knockout Size	1/2 in, 3/4 in

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E143222	cULus Listed	Yes
---------------------	---------	--------------	-----

Additional Information

RoHS Compliant	Yes
----------------	-----

Technical Information

Floor Type	Wood	Service Capacity	Dual
------------	------	------------------	------

Minimum Floor Depth	5 in	Box Capacity	2 Gangs
---------------------	------	--------------	---------

Cable Entry	Through Floor	Box Type	Recessed
-------------	---------------	----------	----------

Depth Behind Device Plates	3.87 in
----------------------------	---------