




adorne Collection  
adorne® Smart Tru-Universal Dimmer with Netatmo, Magnesium  
Part No. WNAL50M1

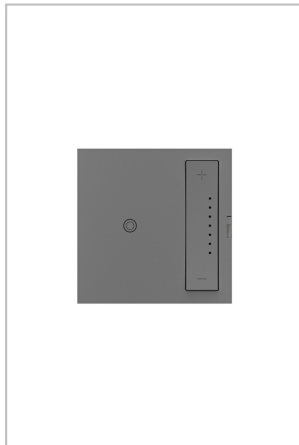

Through Tru-Universal technology, this sofTap® smart dimmer switch works with virtually any 120V dimmable bulb or fixture. Pair with an adorne Wireless Smart Dimmer with Netatmo to gain easy 3-way control. Smart Lighting lets you set the exact lighting you need, from anywhere, adding safety and convenience to your home. And delivering it all with unprecedented range and reliability, adorne® with Netatmo leverages leading Netatmo technology to provide an ideal solution for larger homes with many smart products. Start with the Smart Gateway to establish a robust and dedicated mesh network, then add smart switches, smart dimmer light switches and smart outlets to build a solution that perfectly fits a home's unique space and needs. Made exclusively for use with Wall Plates from the adorne® Collection, sold separately.

## Features & Benefits

Smart Gateway REQUIRED.

Controls and dims lights via smartphones and tablets using the Legrand Home + Control app. Even schedule lights to turn on/off automatically, create groups, set scenes and monitor energy usage.

Works with virtually any 120V dimmable bulb or fixture (excludes 0-10V).

Installs easily in place of an existing switch or dimmer (neutral wire required). For easy 3-way control, pair it with a Wireless Smart Dimmer with Netatmo.

Part of the adorne with Netatmo solution, which flexibly fits a home's unique needs with a variety of supported smart switches, dimmers and outlets (including wireless switches and dimmers).

Features ultra-reliable performance through a robust and dedicated mesh-network. (Established by the Smart Gateway.)

Compatible with other smart products through Amazon Alexa, Google Assistant and Apple HomeKit, as well as with home automation systems.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Complete the look with a stunning, screwless adorne® Wall Plate, not included. Available in a range of contemporary colors and finishes. Coordinate with other designer switches & outlets.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Magnesium
Finish	Metallic	UPC Number	785007380828

Country Of Origin	China	Features	Smart Lighting, With Netatmo
Switch Type	Multi-Location, Single Pole 3-Way, sofTap	Number of Switches	1
Works With	Amazon Alexa, Apple Home Kit, Google Assistant	Device Front Face Size	Full-Size
Device Backbody Size	Plus-Size	Application Sector	Hospitality, Residential
Warranty Type	2-Year Limited	Type	Dimmer
Dimensions			
Product Width US	1.73 in	Product Depth US	1.53 in
Product Height US	4.19 in		
Listing Agencies / 3rd Party Agencies			
cULus ListingNumber	E95219	cULus Listed	Yes
Additional Information			
RoHS Compliant	Yes		
Technical Information			
Load Rating	120V 250W 2.1A (CFL - Reverse Phase Only), 120V 250W 2.1A (EFL - Reverse Phase Only), 120V 250W 2.1A (ELV - Reverse Phase Only), 120V 250W 2.1A (LED - Reverse Phase Only), 120V 450W (ELV - Reverse Phase Only), 120V 450W (Halogen - Reverse Phase Only), 120V 450W (Incandescent - Reverse Phase Only), 120V 450W 3.8A (CFL - Forward Phase Only), 120V 450W 3.8A (EFL - Forward Phase Only), 120V 450W 3.8A (LED - Forward Phase Only), 120V 700W (Halogen - Forward Phase Only), 120V 700W (Incandescent - Forward Phase Only)	Seismic Tested	No
Dimming Compatibility	Forward or Reverse Selectable Phase	Frequency Rating	60 Hz
Number of Wires	4	Number of Gangs	1

Bulb Compatibility	CFL, Fluorescent, Halogen, Incandescent, LED	Number of Poles	Multi-Location, Single Pole 3-Way
Wire Size	#14 - #10 AWG	Requires Neutral Wire	Yes
Indoor/Outdoor	Indoor	Mounting Type	Wall Box
Wire Connection Type	Screw Terminals	Voltage	120 VAC