




adorne Collection  
adorne® Smart Tru-Universal Dimmer with Netatmo, White  
Part No. WNAL50W1

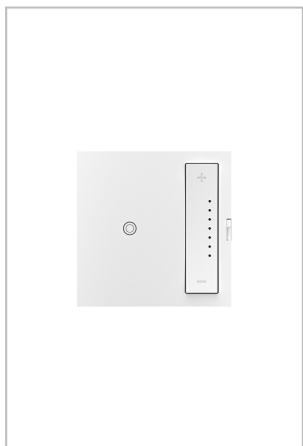

Through Tru-Universal technology, this sofTap® smart dimmer switch works with virtually any 120V dimmable bulb or fixture. Pair with an adorne Wireless Smart Dimmer with Netatmo to gain easy 3-way control. Smart Lighting lets you set the exact lighting you need, from anywhere, adding safety and convenience to your home. And delivering it all with unprecedented range and reliability, adorne® with Netatmo leverages leading Netatmo technology to provide an ideal solution for larger homes with many smart products. Start with the Smart Gateway to establish a robust and dedicated mesh network, then add smart switches, smart dimmer light switches and smart outlets to build a solution that perfectly fits a home's unique space and needs. Made exclusively for use with Wall Plates from the adorne® Collection, sold separately.

## Features & Benefits

Smart Gateway REQUIRED.

Controls and dims lights via smartphones and tablets using the Legrand Home + Control app. Even schedule lights to turn on/off automatically, create groups, set scenes and monitor energy usage.

Works with virtually any 120V dimmable bulb or fixture (excludes 0-10V).

Installs easily in place of an existing switch or dimmer (neutral wire required). For easy 3-way control, pair it with a Wireless Smart Dimmer with Netatmo.

Part of the adorne with Netatmo solution, which flexibly fits a home's unique needs with a variety of supported smart switches, dimmers and outlets (including wireless switches and dimmers).

Features ultra-reliable performance through a robust and dedicated mesh-network. (Established by the Smart Gateway.)

Compatible with other smart products through Amazon Alexa, Google Assistant and Apple HomeKit, as well as with home automation systems.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Complete the look with a stunning, screwless adorne® Wall Plate, not included. Available in a range of contemporary colors and finishes. Coordinate with other designer switches & outlets.

## Specifications

### General Info

|              |                |            |              |
|--------------|----------------|------------|--------------|
| Product Line | Pass & Seymour | Color      | White        |
| Finish       | Gloss          | UPC Number | 785007380811 |

|                                       |   |                        |                              |
|---------------------------------------|---|------------------------|------------------------------|
| Country Of Origin                     | China   | Features               | Smart Lighting, With Netatmo |
| Switch Type                           | Multi-Location, Single Pole 3-Way, sofTap   | Number of Switches     | 1                            |
| Works With                            | Amazon Alexa, Apple Home Kit, Google Assistant  | Device Front Face Size | Full-Size                    |
| Device Backbody Size                  | Plus-Size   | Application Sector     | Hospitality, Residential     |
| Warranty Type                         | 2-Year Limited  | Type                   | Dimmer                       |
| Dimensions                            |   |                        |                              |
| Product Width US                      | 1.73 in   | Product Depth US       | 1.53 in                      |
| Product Height US                     | 4.19 in   |                        |                              |
| Listing Agencies / 3rd Party Agencies |   |                        |                              |
| cULus ListingNumber                   | E95219  | cULus Listed           | Yes                          |
| FCC Compliant                         | Yes   |                        |                              |
| Additional Information                |   |                        |                              |
| RoHS Compliant                        | Yes   |                        |                              |
| Technical Information                 |   |                        |                              |
| Load Rating                           | 120V 250W 2.1A (CFL - Reverse Phase Only), 120V 250W 2.1A (EFL - Reverse Phase Only), 120V 250W 2.1A (ELV - Reverse Phase Only), 120V 250W 2.1A (LED - Reverse Phase Only), 120V 450W (ELV - Reverse Phase Only), 120V 450W (Halogen - Reverse Phase Only), 120V 450W (Incandescent - Reverse Phase Only), 120V 450W 3.8A (CFL - Forward Phase Only), 120V 450W 3.8A (EFL - Forward Phase Only), 120V 450W 3.8A (LED - Forward Phase Only), 120V 700W (Halogen - Forward Phase Only), 120V 700W (Incandescent - Forward Phase Only) | Seismic Tested         | No                           |
| Dimming Compatibility                 | Forward or Reverse Selectable Phase   | Frequency Rating       | 60 Hz                        |
| Number of Wires                       | 4   | Number of Gangs        | 1                            |

|                      |  |                       |                                   |
|----------------------|--|-----------------------|-----------------------------------|
| Bulb Compatibility   | CFL, Fluorescent, Halogen, Incandescent, LED | Number of Poles       | Multi-Location, Single Pole 3-Way |
| Wire Size            | #14 - #10 AWG                                | Requires Neutral Wire | Yes                               |
| Indoor/Outdoor       | Indoor                                       | Mounting Type         | Wall Box                          |
| Wire Connection Type | Screw Terminals                              | Voltage               | 120 VAC                           |