




Pass and Seymour  
Wide Slide Series CFL/LED/Incandescent Single Pole/3-Way Paddle Slide Dimmer, Preset, Tri-Color  
Part No. WSCL453PTCCCV4

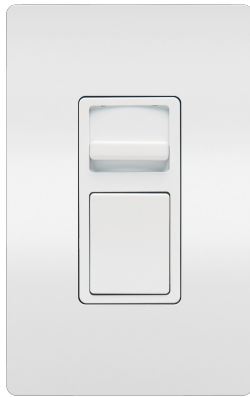

Works with select dimmable CFL/LED or incandescent lighting loads and features a sleek, sculpted ergonomic design for smooth, easy operation and precise control.

## Features & Benefits

Convenient Operation - Combines ON/OFF Decorator style switch with separate slider for dimming control	Constant memory returns lights to previous level after a power failure
Sleek, ergonomic design that matches well with other decorator products	Higher ratings
Single pole and 3-way operation	Screw-pressure-plate back wire terminals to save time, space and money
Wattage Rating: 450 W (LED & CFL), 700 W (Incandescent)	

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Ivory, Light Almond, White
Country Of Origin	China	Switch Type	Push, Slider
Number of Switches	1	Warranty Type	Limited Lifetime Warranty

### Dimensions

Product Width US	1.75 in	Product Depth US	1.25 in
Product Height US	4.25 in		

### Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

### Technical Information

Bulb Compatibility	CFL, Incandescent, LED	Number of Poles	3-Way, Single Pole
--------------------	------------------------	-----------------	--------------------

---

Wattage

450 W

Voltage

120.0 V

---