




Pass and Seymour  
**Wide Slide Series CFL/LED/Incandescent Single Pole/3-Way Paddle Slide Dimmer, Preset, Tri-Color**  
Part No. WSCL453PTCCCV4

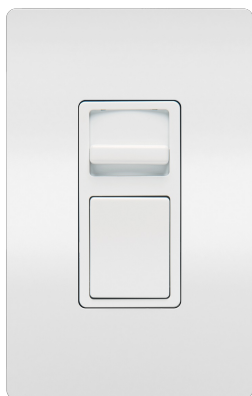

## Features & Benefits

Convenient Operation - Combines ON/OFF Decorator style switch with separate slider for dimming control	Constant memory returns lights to previous level after a power failure
Sleek, ergonomic design that matches well with other decorator products	Higher ratings
Single pole and 3-way operation	Screw-pressure-plate back wire terminals to save time, space and money
Wattage Rating: 450 W (LED & CFL), 700 W (Incandescent)	

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Ivory, Light Almond, White
Finish	Matte	UPC Number	785007039351
Country Of Origin	China	Product Series	Decorator
Features	Color Change Kit, Low-End Trim (Dim Range)	Switch Type	Rocker, Single Pole 3-Way, Slider
Number of Switches	1	Application Sector	Commercial, Residential
Warranty Type	Limited Lifetime Warranty		

### Dimensions

Product Width US	1.75 in	Product Depth US	1.25 in
Product Height US	4.25 in		

### Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

Technical Information

Preset	Yes	Load Rating	120V 450W (CFL), 120V 450W (LED), 120V 700W (Halogen), 120V 700W (Incandescent)
Dimming Compatibility	Forward Phase	Frequency Rating	60 Hz
Number of Poles	Single Pole 3-Way	Wire Size	#14 - #10 AWG
Requires Neutral Wire	No	Indoor/Outdoor	Indoor
Mounting Type	Wall Box	Wire Connection Type	Screw Terminals
Voltage	120 VAC	Load Type	CFL, Halogen, Incandescent, LED