



## Cable management that's secure and installs 50% faster

J-Hooks provide an easy-to-install, non-continuous cable support for all types of telecommunication, data and power cabling. They also are perfect for low voltage building cable management and fire protection cabling.

Our CJH Series is engineered to provide stress-free cable support for multiple cables and features a structural design for optimal strength and tapered edges to reduce cable sheath damage. Multiple pre-drilled holes reduce on-site modification at installation. J-Hooks can be attached to a variety of structures and are available with multiple attachment options that allow quick and easy cable installation virtually anywhere.

The CJHP Series J-Hooks are plenum rated, plastic coated and feature a built in latch that allows you to lock the bendable flap into place – and unlock easier. CJHP hooks also combine the best features of both metal and plastic, providing strength and a slick, no-burr surface to make pulling cable easy. All CJHP hooks are plenum safe.

### Features & Benefits

#### CJH Series – Steel J-Hooks

- **Broad product line.** CJH Series J-Hooks are available in 4 sizes ¾" to 4" sizes with a cable retainer clip (Patent Pending) and has multiple attachment options.
- **Sturdy steel construction.** CJH Series J-Hooks have a wider base and provides optimal support for electrical and high-performance data cables, including CAT 5e, CAT 5, CAT 6A, CAT 7 and fiber optic.
- **Smooth tapered edges.** Smooth edges of CJH Series J-Hooks reduces pressure points for ultimate cable protections.
- **Simple single person installation.** Labor savings.
- **Highest cable fill capacity.** CJH Series J-Hooks have the highest fill capacity on the market and are engineered to accommodate future emerging data cables.
- **Manufactured using over 70% recycled steel.** CJH Series J-Hooks are manufactured using over 70% recycled steel. Great for recycling and the environment.
- **UL load and anti-corrosion tested.** cULus listed.
- **RoHS compliant.** Environmentally friendly.
- **Meets TIA-568-C & TIA 569-C and complies with EN 50174-2.** Ensures that software and applications running on the network are able to perform as designed and work seamlessly together.

#### CJHP Series – Plastic J-Hooks

- **Cable containment latch.** CJHP Services J-Hooks integral catch quickly opens and closes for easy moves, adds or changes. Available in 4 sizes 1" to 4" sizes and has multiple attachment options.
- **Smooth easy-slide polypropylene construction.** CJHP Series J-Hooks allow cables to slide with 50% less pulling tension.
- **Safe for use in plenum spaces.** CJHP Series J-Hooks are UL listed safe for use in plenum spaces.
- **Simple single person installation.** Labor savings.
- **UL load and anti-corrosion tested.** cULus listed.
- **RoHS compliant.** Environmentally friendly.
- **Meets TIA-568-C & TIA 569-C and complies with EN 50174-2.** Ensures that software and applications running on the network are able to perform as designed and work seamlessly together.

### Vertical Markets

- Commercial
- Hospitality
- Education
- Entertainment


### Compliance

- cULus Listed UL31TS
- RoHS Compliant

### Country of Origin

- Cablofil® CJH Series and CJHP Series J-Hooks are made in the USA and assembled in Mexico.

**CJH Series Steel J-Hooks Specifications**

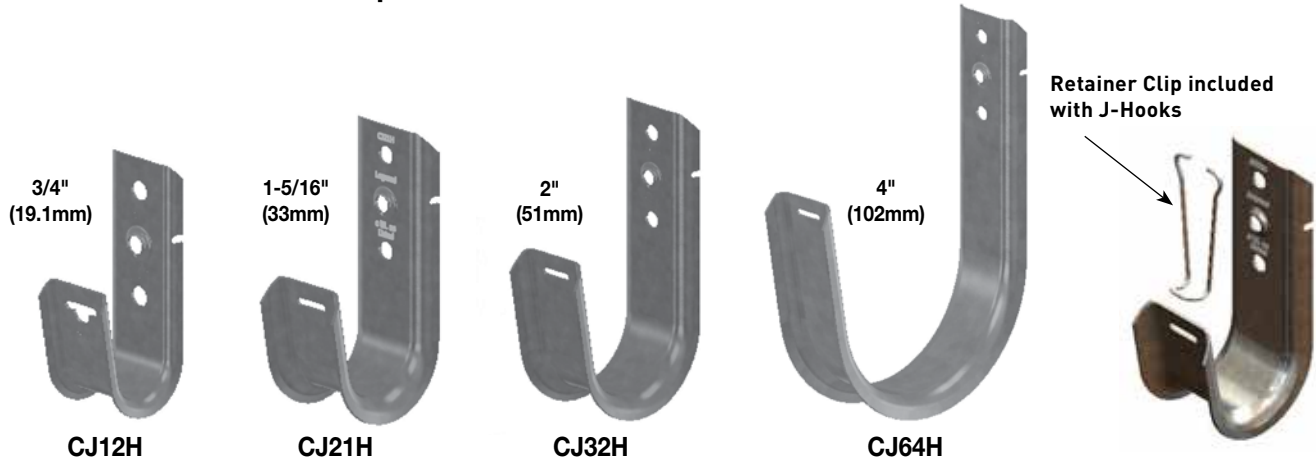

CJH Series J-Hooks Load/Fill Capacity Table					
	HOOK SIZE	LOAD CAPACITY	CABLE CAPACITY		
	IN	LBS	4-PAIR UTP CAT 5E	CAT 6	CAT 6A
CJ12H	3/4"	65	34	23	13
CJ21H	1-5/16"	65	61	42	24
CJ32H	2"	65	119	81	48
CJ64H	4"	65	417	284	167

CJH Series J-Hooks Attachment Options				
W 	AC 	AC6 	HOK24 	HOK58 
Bat Wing 12 Gage – 1/4" & 3/8" ATR	90° Angled Clip – 1/4" hole	90° Angled Clip – 3/8" hole	Knock-On Steel Beam Clamp – 1/8" to 1/4"	Knock-On Steel Beam Clamp – 5/16" to 1/2"
PBC 	ACPBC 	SSBC 	ACSSB 	ACHOK24 
Pressed Beam Clamp – up to 1/2"	Angled Clip & Pressed Beam Clamp – up to 1/2"	Assembled to SSBC – 1/8" to 1/2"	Angled Clip & SSBC – swivels 360°	Knock-on Clamp & Angled Clip – swivels 360°

**PART NUMBERING EXAMPLE**  
**CJ12HHOK24**

**J-HOOK** ——— **ATTACHMENT**  
 Choose between ——— Choose option  
 CJ12H, CJ21H, CJ32H & CJ64H

**CJH Series Steel J-Hooks Ordering Information**

<b>CJ12H – 3/4" J-HOOK</b>					
	<b>PKG QTY</b>	<b>HOOK SIZE (In.)</b>	<b>DESCRIPTION</b>	<b>WEIGHT (Lbs.)</b>	<b>PG</b>
<b>CJ12H</b>	50	3/4"	J-Hook Wide Base w/Retainer	4.5	F000247
<b>CJ12HAC</b>	50	3/4"	J-Hook Wide/Ret - 90° Angle Clip 1/4 Rod	5.8	F000248
<b>CJ12HW*</b>	50	3/4"	J-Hook Wide/Ret - Batwing Clip	5.75	F000249
<b>CJ12HAC6</b>	50	3/4"	J-Hook Wide/Ret 90° Angle Clip 3/8 Rod	5.7	F000250
<b>CJ12HSSBC</b>	50	3/4"	J-Hook Wide/Ret - Screw on Spring Steel Beam Clip 1/2	7.3	F000259
<b>CJ12HACHOK24</b>	50	3/4"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 1/8-1/4	8.35	F000252
<b>CJ12HACHOK58</b>	50	3/4"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 5/16-1/2	8.35	F000253
<b>CJ12HACPBC</b>	50	3/4"	J-Hook Wide/Ret - 90° Swivel Screw on Beam Clip 1/2	11.5	F000254
<b>CJ12HACSSBC</b>	50	3/4"	J-Hook Wide/Ret - 90° Swivel Screw on Beam Clip 1/2	8.6	F000255
<b>CJ12HHOK24</b>	50	3/4"	J-Hook Wide/Ret - Knock on Beam Clamp 1/8-1/4	5.8	F000256
<b>CJ12HHOK58</b>	50	3/4"	J-Hook Wide/Ret - Knock on Beam Clamp 5/16-1/2	5.8	F000257
<b>CJ12HPBC</b>	50	3/4"	J-Hook Wide/Ret - Screw on Beam Clamp 1/2	10.2	F000258

<b>CJ21H – 1 5/16" J-HOOK</b>					
	<b>PKG QTY</b>	<b>HOOK SIZE (In.)</b>	<b>DESCRIPTION</b>	<b>WEIGHT (Lbs.)</b>	<b>PG</b>
<b>CJ21H</b>	50	1-5/16"	J-Hook Wide Base w/Retainer	8.5	F000260
<b>CJ21HAC</b>	50	1-5/16"	J-Hook Wide/Ret - 90° Angle Clip 1/4 Rod	9.8	F000261
<b>CJ21HW*</b>	50	1-5/16"	J-Hook Wide/Ret - Batwing Clip	9.75	F000262
<b>CJ21HAC6</b>	50	1-5/16"	J-Hook Wide/Ret - 90° Angle Clip 3/8 Rod	9.7	F000263
<b>CJ21HSSBC</b>	50	1-5/16"	J-Hook Wide/Ret - Screw on Spring Steel Beam Clip 1/2	11.3	F000272
<b>CJ21HACHOK24</b>	50	1-5/16"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 1/8-1/4	12.35	F000265
<b>CJ21HACHOK58</b>	50	1-5/16"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 5/16-1/2	12.35	F000266
<b>CJ21HACPBC</b>	50	1-5/16"	J-Hook Wide/Ret - 90° Swivel Screw on Beam Clip 1/2	15.5	F000267
<b>CJ21HACSSBC</b>	50	1-5/16"	J-Hook Wide/Ret - 90° Swivel Screw on Spring Steel Beam Clip 1/2	12.6	F000268
<b>CJ21HHOK24</b>	50	1-5/16"	J-Hook Wide/Ret - Knock on Beam Clip 1/8-1/4	9.8	F000269
<b>CJ21HHOK58</b>	50	1-5/16"	J-Hook Wide/Ret - Knock on Beam Clip 5/16-1/2	9.8	F000270
<b>CJ21HPBC</b>	50	1-5/16"	J-Hook Wide/rRet - Screw on Beam Clip 1/2	14.2	F000271

<b>CJ32H – 2" J-HOOK</b>					
	<b>PKG QTY</b>	<b>HOOK SIZE (In.)</b>	<b>DESCRIPTION</b>	<b>WEIGHT (Lbs.)</b>	<b>PG</b>
<b>CJ32H</b>	50	2"	J-Hook Wide Base w/Retainer	10.3	F000273
<b>CJ32HAC</b>	50	2"	J-Hook Wide/Ret - 90° Angle Clip 1/4 Rod	11.6	F000274
<b>CJ32AHW*</b>	50	2"	J-Hook Wide/Ret - Batwing Clip	11.55	F000275
<b>CJ32HAC6</b>	50	2"	J-Hook Wide/Ret - 90° Angle Clip 3/8 rod	11.5	F000276
<b>CJ32HSSBC</b>	50	2"	J-Hook Wide/Ret - Screw on Spring Steel Beam Clip 1/2	13.1	F000285
<b>CJ32HACHOK24</b>	50	2"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 1/8-1/4	14.15	F000278
<b>CJ32HACHOK58</b>	50	2"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 5/16-1/2	14.15	F000279
<b>CJ32HACPBC</b>	50	2"	J-Hook Wide/Ret - 90° Swivel Screw on Press Beam Clip 1/2	17.3	F000280
<b>CJ32HACSSBC</b>	50	2"	J-Hook Wide/Ret - 90° Swivel Screw on Spring Steel Beam Clip 1/2	14.4	F000281
<b>CJ32HHOK24</b>	50	2"	J-Hook Wide/Ret - Knock on Beam Clip 1/8-1/4	11.6	F000282
<b>CJ32HHOK58</b>	50	2"	J-Hook Wide/Ret - Knock on Beam Clip 5/16-1/2	11.6	F000283
<b>CJ32PBC</b>	50	2"	J-Hook Wide/Ret - Screw on Beam Clip 1/2	13.8	F000284

\* Works with both 1/4 x 20 and 3/8 x 16 rod

## CJH Series Steel J-Hooks Ordering Information

<b>CJ64H – 4" J-HOOK</b>					
	<b>PKG QTY</b>	<b>HOOK SIZE (In. )</b>	<b>DESCRIPTION</b>	<b>WEIGHT (Lbs.)</b>	<b>PG</b>
<b>CJ64H</b>	25	4"	J-Hook Wide Base w/Retainer	9.25	F000286
<b>CJ64HAC</b>	25	4"	J-Hook Wide/Ret - 90° Angle Clip 1/4 Rod	9.9	F000287
<b>CJ64HW*</b>	25	4"	J-Hook Wide/Ret - Batwing Clip	10	F000288
<b>CJ64HAC6</b>	25	4"	J-Hook Wide/Ret - 90° Angle Clip 3/8 Rod	9.85	F000289
<b>CJ64HSSBC</b>	25	4"	J-Hook Wide/Ret - Screw on Beam Clip 1/2	10.65	F000298
<b>CJ64HACHOK24</b>	25	4"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 1/8-1/4	11.18	F000291
<b>CJ64HACHOK58</b>	25	4"	J-Hook Wide/Ret - 90° Swivel Knock on Beam Clip 5/16-1/2	11.18	F000292
<b>CJ64ACPBC</b>	25	4"	J-Hook Wide/Ret - Screw on Press Beam Clip 1/2	12.75	F000293
<b>CJ64ACSSBC</b>	25	4"	J-Hook Wide/Ret - Screw on Spring Steel Beam Clip 1/2	11.3	F000294
<b>CJ64AHOK24</b>	25	4"	J-Hook Wide/Ret - Knock on Beam Clip 1/8-1/4	9.9	F000295
<b>CJ64HOK58</b>	25	4"	J-Hook Wide/Ret - Knock on Beam Clip 5/16-1/2	9.9	F000296
<b>CJ64PBC</b>	25	4"	J Hook Wide/Ret - Screw on Beam Clip 1/2	12.1	F000297

\* Works with both 1/4 x 20 and 3/8 x 16 rod

**CJHP Series Plastic J-Hooks Ordering Information**




1"  
(25mm)




**CJ16HP**

2"  
(51mm)

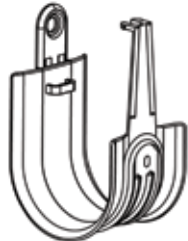


**CJ32HP**

3"  
(76mm)

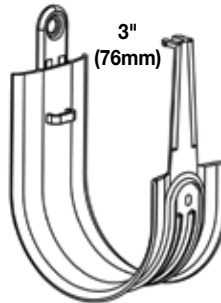

**CJ48HP**

4"  
(102mm)

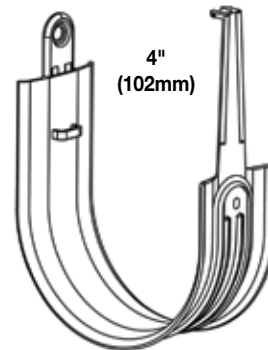


**CJ64HP**

<b>CJHP Load Capacity Table</b>					
	HOOK SIZE	LOAD CAPACITY	CABLE CAPACITY		
	IN.	LBS.	4-PAIR UTP CAT 5E	CAT 6	2 STRAND FIBER OPTIC
<b>CJ16HP</b>	1"	17	20	15	20
<b>CJ32HP</b>	2"	17	90	60	90
<b>CJ48HP</b>	3"	20	200	150	200
<b>CJ64HP</b>	4"	17	330	220	330

**NOTE:** Standard color is white. Additional colors available are black, blue and red.

**CJHP Series Plastic J-Hooks Attachment Options**

CJHP Series J-Hooks Attachment Options				
W 	AC 	AC6 	HOK24 	HOK58 
Bat Wing 12 Gage – 1/4" ATR	90° Angled Clip – 1/4" hole	90° Angled Clip – 3/8" hole	Knock-On Steel Beam Clamp – 1/8" to 1/4"	Knock-On Steel Beam Clamp – 5/16" to 1/2"
PBC 	ACPBC 	SSBC 	ACSSB 	ACHOK24 
Pressed Beam Clamp – up to 1/2"	Angled Clip & Pressed Beam Clamp – up to 1/2"	Assembled to SSBC – 1/8" to 1/2"	Angled Clip & SSBC – swivels 360°	Knock-on Clamp & Angled Clip – swivels 360°

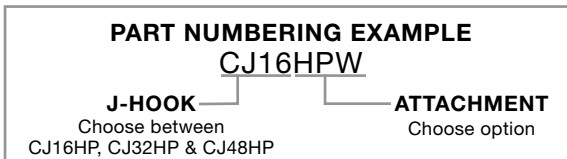

**CJHP Series Plastic J-Hooks Ordering Information**

<b>CJ16HP</b>					
	<b>PKG QTY</b>	<b>HOOK SIZE (In. )</b>	<b>DESCRIPTION</b>	<b>WEIGHT (Lbs.)</b>	<b>PG</b>
<b>CJ16HP</b>	25	1"	Basic Plastic Coated JHook w/Latch	3	F000051
<b>CJ16HPBL</b>	25	1"	Basic Black Plastic Coated Jhook w/Latch	3	F000299
<b>CJ16HPBU</b>	25	1"	Basic Blue Plastic Coated Jhook w/Latch	3	F000300
<b>CJ16HPRD</b>	25	1"	Basic Red Plastic Coated Jhook w/Latch	3	F000301
<b>CJ16HPAC</b>	25	1"	Plastic Coated JHook w/Latch and 90°Angle Clip 1/4 rod	4	F000060
<b>CJ16HPW*</b>	25	1"	Plastic Coated Jhook w/Latch and Batwing Clip	4	F000059
<b>CJ16HPAC6</b>	25	1"	Plastic Coated JHook w/Latch and 90° Angle Clip 3/8 rod	4	F000302
<b>CJ16HPHOK24</b>	25	1"	Plastic Coated JHook w/Latch and Knock on Beam Clip 1/8 - 1/4	5	F000304
<b>CJ16HPHOK58</b>	25	1"	Plastic Coated JHook w/Latch and Knock on Beam Clip 5/16 - 1/2	6	F000305
<b>CJ16HPACPBC</b>	25	1"	Plastic Coated JHook w/Latch and Screw on Beam Clip 1/2	7	F000306
<b>CJ16HPACSSBC</b>	25	1"	Plastic Coated JHook w/Latch and Screw on Beam Clip 1/2	5	F000307
<b>CJ16HPHOK24</b>	25	1"	Plastic Coated JHook w/Latch and Knock on Beam Clip 1/8 - 1/4	4	F000308
<b>CJ16HPHOK58</b>	25	1"	Plastic Coated JHook w/Latch and Knock on Beam Clip 5/16 - 1/2	4	F000309
<b>CJ16HPPBC</b>	25	1"	Plastic Coated Jhook w/Latch and Screw on Beam Clip 1/2	6	F000310
<b>CJ16HPSSBC</b>	25	1"	Plastic Coated JHook w/Latch and Screw on Beam Clip 1/2	5	F000311

<b>CJ32HP</b>					
	<b>PKG QTY</b>	<b>HOOK SIZE (In. )</b>	<b>DESCRIPTION</b>	<b>WEIGHT (Lbs.)</b>	<b>PG</b>
<b>CJ32HP</b>	25	2"	Basic Plastic Coated JHook w/Latch	4	F000052
<b>CJ32HPBL</b>	25	2"	Basic Black Plastic Coated JHook w/Latch	4	F000312
<b>CJ32HPBU</b>	25	2"	Basic Blue Plastic Coated JHook w/Latch	4	F000313
<b>CJ32HPRD</b>	25	2"	Basic Red Plastic Coated JHook w/Latch	4	F000314
<b>CJ32HPAC</b>	25	2"	Plastic Coated JHook w/Latch and 90° Angle Clip 1/4 rod	5	F000062
<b>CJ32HPW*</b>	25	2"	Plastic Coated w/Latch JHook and Batwing Clip	5	F000061
<b>CJ32HPAC6</b>	25	2"	Plastic Coated Jhook w/Latch and 90° Angle Clip 3/8 rod	5	F000315
<b>CJ32HPHOK24</b>	25	2"	Plastic Coated JHook w/Latch and Knock on Beam Clip 1/8 - 1/4	6	F000317
<b>CJ32HPHOK58</b>	25	2"	Plastic Coated JHook w/Latch and Knock on Beam Clip 5/16 - 1/2	7	F000318
<b>CJ32HPACPBC</b>	25	2"	Plastic Coated JHook w/Latch and Screw on Press Beam Clip 1/2	8	F000319
<b>CJ32HPACSSBC</b>	25	2"	Plastic Coated Jhook w/Latch and Screw on Beam Clip 1/2	6	F000320
<b>CJ32HPHOK24</b>	25	2"	Plastic Coated JHook w/Latch and Knock on beam Clip 1/8 - 1/4	5	F000321
<b>CJ32HPHOK58</b>	25	2"	Plastic Coated JHook w/Latch and Knock on Beam Clip 5/16 - 1/2	5	F000322
<b>CJ32HPPBC</b>	25	2"	Plastic Coated JHook w/Latch and Screw on Press Beam Clip 1/2	7	F000323
<b>CJ32HPSSBC</b>	25	2"	Plastic Coated JHook w/Latch and Screw on Beam Clip 1/2	6	F000246

\* Works with both 1/4 x 20 and 3/8 x 16 rod

**CJHP Series Plastic J-Hooks Ordering Information**

<b>CJ48HP</b>					
	<b>PKG QTY</b>	<b>HOOK SIZE (In. )</b>	<b>DESCRIPTION</b>	<b>WEIGHT (Lbs.)</b>	<b>PG</b>
<b>CJ48HP</b>	25	3"	Basic Plastic Coated Jhook w/Latch	9	F000053
<b>CJ48HPBL</b>	25	3"	Basic Black Plastic Coated Jhook w/Latch	9	F000324
<b>CJ48HPBU</b>	25	3"	Basic Blue Plastic Coated Jhook w/Latch	9	F000325
<b>CJ48HPRD</b>	25	3"	Basic Red Plastic Coated Jhook w/Latch	9	F000326
<b>CJ48HPAC</b>	25	3"	Plastic Coated JHook w/Latch and 90° Angle Clip 1/4 rod	10	F000064
<b>CJ48HPW*</b>	25	3"	Plastic Coated Jhook w/Latch and Batwing Clip	10	F000063
<b>CJ48HPAC6</b>	25	3"	Plastic Coated JHook w/Latch and 90° Angle Clip 3/8 rod	10	F000327
<b>CJ48HPHOK24</b>	25	3"	Plastic Coated JHook w/Latch and Knock on Beam Clip 1/8 - 1/4	12	F000329
<b>CJ48HPHOK58</b>	25	3"	Plastic Coated Jhook w/Latch and Knock on Beam Clip 5/16 - 1/2	12	F000330
<b>CJ48HPACPBC</b>	25	3"	Plastic Coated JHook w/Latch and Screw on Press Beam Clip 1/2	13	F000331
<b>CJ48HPACSSBC</b>	25	3"	Plastic Coated JHook w/Latch and Screw on Beam Clip 1/2	12	F000332
<b>CJ48HPHOK24</b>	25	3"	Plastic Coated JHook w/Latch and Knock on Beam Clip 1/8 - 1/4	11	F000333
<b>CJ48HPHOK58</b>	25	3"	Plastic Coated JHook w/Latch and Knock on Beam Clip 5/16 - 1/2	10	F000334
<b>CJ48HPPBC</b>	25	3"	Plastic Coated JHook w/Latch and Screw on Press Beam Clip 1/2	12	F000335
<b>CJ48HPSSBC</b>	25	3"	Plastic Coated JHook w/Latch and Screw on Beam Clip 1/2	11	F000336

<b>CJ64HP</b>					
	<b>PKG QTY</b>	<b>HOOK SIZE (In. )</b>	<b>DESCRIPTION</b>	<b>WEIGHT (Lbs.)</b>	<b>PG</b>
<b>CJ64HP</b>	25	4"	Basic Plastic Coated Jhook w/Latch	11	F000337
<b>CJ64HPBL</b>	25	4"	Basic Black Plastic Coated Jhook w/Latch	11	F000338
<b>CJ64HPBU</b>	25	4"	Basic Blue Plastic Coated Jhook w/Latch	11	F000339
<b>CJ64HPRD</b>	25	4"	Basic Red Plastic Coated Jhook w/Latch	11	F000340
<b>CJ64HPAC</b>	25	4"	Plastic Coated JHook w/Latch and 90° Angle Clip 1/4 rod	12	F000341
<b>CJ64HPW*</b>	25	4"	Plastic Coated Jhook w/Latch and Batwing clip	12	F000342
<b>CJ64HPAC6</b>	25	4"	Plastic Coated JHook w/Latch and 90° Angle Clip 3/8 rod	12	F000343
<b>CJ64HPHOK24</b>	25	4"	Plastic Coated JHook w/Latch and Knock on Beam Clip 1/8 - 1/4	13	F000345
<b>CJ64HPHOK58</b>	25	4"	Plastic Coated JHook w/Latch and Knock on Beam Clip 5/16 - 1/2	14	F000346
<b>CJ64HPACPBC</b>	25	4"	Plastic Coated JHook w/Latch and Screw on Press Beam Clip 1/2	15	F000347
<b>CJ64HPACSSBC</b>	25	4"	Plastic Coated JHook w/Latch and Screw on Beam Clip 1/2	13	F000348
<b>CJ64HPHOK24</b>	25	4"	Plastic Coated JHook w/Latch and Knock on Beam Clip 1/8 - 1/4	12	F000349
<b>CJ64HPHOK58</b>	25	4"	Plastic Coated JHook w/Latch and Knock on Beam Clip 5/16 - 1/2	12	F000350
<b>CJ64HPPBC</b>	25	4"	Plastic Coated JHook w/Latch and Screw on Press Beam Clip 1/2	14	F000351
<b>CJ64HPSSBC</b>	25	4"	Plastic Coated Jhook w/Latch and Screw on Beam Clip 1/2	12	F000352

\* Works with both 1/4 x 20 and 3/8 x 16 rod

**BRIDLE RINGS**









Bridle rings are a simple option for smaller bundles of communication or data cabling.

	<b>PKG QTY</b>	<b>RING SIZE (IN)</b>	<b>DESCRIPTION</b>	<b>WEIGHT (LBS)</b>	<b>EZ</b>
<b>CJ4T125</b>	100	1 ¼	Bridle Ring ¼ x 20	6	F000042
<b>CJ4T2</b>	100	2	Bridle Ring ¼ x 20	9	F000043



### J-Hooks Attachments Ordering Information


Use these attachment options to create your own custom J-Hook combinations. Sold in quantities of 100.

CJ Attachment Mounting Hardware			
 CJ24 Knock-on steel beam clamp – 1/8" to 1/4"	 CJ58 Knock-on steel beam clamp – 5/16" to 1/2"	 CJFMP Knock-on spring steel beam clamp – 1/8" to 1/2"	 CJBC Pressed beam clamp – up to 1/2"
 CJSSBC Spring steel beam clamp 1/8" – 1/2"	 CJZ14 1/8" – 1/4" Z Purlin	 CJC14 1/8" – 1/4" C Purlin	 CJBW Bat wing 12 gage – 1/4" & 3/8" ATR

### Field Creation of J-Hook Trees

Use J-Hook extension bracket to create your own custom J-Hook trees.

Catalog No./Item	Description/Specifications
CJHEB	Wide Style J-Hook Extension Bracket

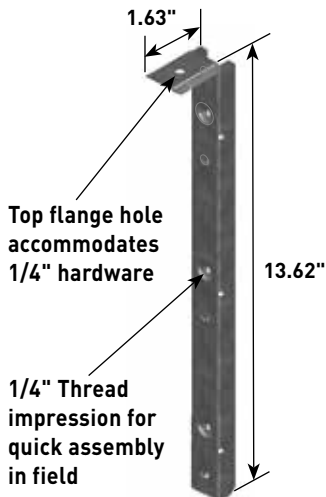

#### Features

- Allows for field creation of custom J-Hook Trees of any of the four (4) sizes available up to three (3) tiers
- Single side or back-to-back
- Sold as each
- Complies with NEC & meets TIA568-C & 569-C



CJHEB Bracket shown with 3 tiers of CJ32H's.

### Factory Assembled J-Hooks with Retainer Clips Trees Ordering Information

J-Hook Trees are the ideal solution for segregating up to five runs of cable following the same cable pathway. They are ready to use with no assembly required in multiple sizes and attachment methods.


These items are not stocked in our inventory. Please contact the manufacturer for shipping information, pricing and other configurations.



CJHEB Shown with 3 tiers of CJ32H's mounted back-to-back.

CJH TREES					
	HOOK COUNT	WEIGHT (LBS)		HOOK COUNT	WEIGHT (LBS)
<b>1-5/16" VERTICAL TREE SUPPORTS</b>			<b>2" VERTICAL TREE SUPPORTS</b>		
CJ21H-EB-2	2	1.4	CJ32H-EB-2	2	1.6
CJ21H-EB-3	3	2.4	CJ32H-EB-3	3	2.6
CJ21H-EB-4	4	3.4	CJ32H-EB-4	4	3.6
CJ21H-EB-5	5	3.9	CJ32H-EB-5	5	4.1
<b>w/ ANGLE CLIP</b>			<b>w/ ANGLE CLIP</b>		
CJ21H-AC-EB-2	2	1.4	CJ32H-AC-EB-2	2	1.6
CJ21H-AC-EB-3	3	2.4	CJ32H-AC-EB-3	3	2.6
CJ21H-AC-EB-4	4	3.4	CJ32H-AC-EB-4	4	3.6
CJ21H-AC-EB-5	5	3.9	CJ32H-AC-EB-5	5	4.1
<b>w/ BEAM CLAMP</b>			<b>w/ BEAM CLAMP</b>		
CJ21H-PBC-EB-2	2	1.9	CJ32H-PBC-EB-2	2	2.1
CJ21H-PBC-EB-3	3	2.4	CJ32H-PBC-EB-3	3	2.6
CJ21H-PBC-EB-4	4	3.4	CJ32H-PBC-EB-4	4	3.6
CJ21H-PBC-EB-5	5	4.4	CJ32H-PBC-EB-5	5	4.6
<b>4" VERTICAL TREE SUPPORTS</b>			<b>4" VERTICAL TREE SUPPORTS</b>		
CJ64H-EB-2	2	1.5	CJ64H-EB-2	2	1.5
CJ64H-EB-3	3	2.2	CJ64H-EB-3	3	2.2
CJ64H-EB-4	4	-	CJ64H-EB-4	4	-
CJ64H-EB-5	5	3.6	CJ64H-EB-5	5	3.6
<b>w/ ANGLE CLIP</b>			<b>w/ ANGLE CLIP</b>		
CJ64H-AC-EB-2	2	2	CJ64H-AC-EB-2	2	2
CJ64H-AC-EB-3	3	3	CJ64H-AC-EB-3	3	3
CJ64H-AC-EB-4	4	4	CJ64H-AC-EB-4	4	4
CJ64H-AC-EB-5	5	4.5	CJ64H-AC-EB-5	5	4.5
<b>w/ BEAM CLAMP</b>			<b>w/ BEAM CLAMP</b>		
CJ64H-PBC-EB-2	2	2.5	CJ64H-PBC-EB-2	2	2.5
CJ64H-PBC-EB-3	3	3	CJ64H-PBC-EB-3	3	3
CJ64H-PBC-EB-4	4	4	CJ64H-PBC-EB-4	4	4
CJ64H-PBC-EB-5	5	5	CJ64H-PBC-EB-5	5	5


CJHP TREES					
	HOOK COUNT	WEIGHT (LBS)		HOOK COUNT	WEIGHT (LBS)
<b>1" VERTICAL TREE SUPPORTS WITH PLASTIC COATED HOOKS</b>			<b>2" VERTICAL TREE SUPPORTS WITH PLASTIC COATED HOOKS</b>		
CJ16HP-EB-2	2	1.4	CJ32HP-EB-2	2	1.6
CJ16HP-EB-3	3	2.4	CJ32HP-EB-3	3	2.6
CJ16HP-EB-4	4	3.4	CJ32HP-EB-4	4	3.6
CJ16HP-EB-5	5	3.9	CJ32HP-EB-5	5	4.1
<b>W/ ANGLE CLIP</b>			<b>W/ ANGLE CLIP</b>		
CJ16HP-AC-EB-2	2	1.4	CJ32HP-AC-EB-2	2	1.6
CJ16HP-AC-EB-3	3	2.4	CJ32HP-AC-EB-3	3	2.6
CJ16HP-AC-EB-4	4	3.4	CJ32HP-AC-EB-4	4	3.6
CJ16HP-AC-EB-5	5	3.9	CJ32HP-AC-EB-5	5	4.1
<b>W/ BEAM CLAMP</b>			<b>W/ BEAM CLAMP</b>		
CJ16HP-PBC-EB-2	2	1.9	CJ32HP-PBC-EB-2	2	2.1
CJ16HP-PBC-EB-3	3	2.4	CJ32HP-PBC-EB-3	3	2.6
CJ16HP-PBC-EB-4	4	3.4	CJ32HP-PBC-EB-4	4	3.6
CJ16HP-PBC-EB-5	5	4.4	CJ32HP-PBC-EB-5	5	4.6
<b>3" VERTICAL TREE SUPPORTS WITH PLASTIC COATED HOOKS</b>			<b>3" VERTICAL TREE SUPPORTS WITH PLASTIC COATED HOOKS</b>		
CJ48HP-EB-2	2	2	CJ48HP-EB-2	2	2
CJ48HP-EB-3	3	2	CJ48HP-EB-3	3	2
CJ48HP-EB-4	4	4	CJ48HP-EB-4	4	4
CJ48HP-EB-5	5	4	CJ48HP-EB-5	5	4
<b>W/ ANGLE CLIP</b>			<b>W/ ANGLE CLIP</b>		
CJ48HP-AC-EB-2	2	2	CJ48HP-AC-EB-2	2	2
CJ48HP-AC-EB-3	3	3	CJ48HP-AC-EB-3	3	3
CJ48HP-AC-EB-4	4	4	CJ48HP-AC-EB-4	4	4
CJ48HP-AC-EB-5	5	4	CJ48HP-AC-EB-5	5	4
<b>W/ BEAM CLAMP</b>			<b>W/ BEAM CLAMP</b>		
CJ48HP-PBC-EB-2	2	2	CJ48HP-PBC-EB-2	2	2
CJ48HP-PBC-EB-3	3	3	CJ48HP-PBC-EB-3	3	3
CJ48HP-PBC-EB-4	4	4	CJ48HP-PBC-EB-4	4	4
CJ48HP-PBC-EB-5	5	4	CJ48HP-PBC-EB-5	5	4

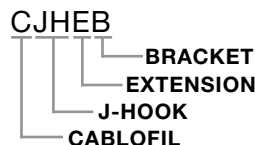



**NOTE: All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.**

---

 **NOTE:** The paper used to print this document is an environmentally responsible paper with 10% post consumer waste, with FSC and SFI Chain of Custody certifications, Lacey Act compliant. 100% of the electricity used to manufacture Flo sheets is generated with Green-e certified renewable energy.



**Legrand, North America**  
60 Woodlawn Street  
West Hartford, CT 06110  
1.877.BY.LEGRAND (295.3472)  
[www.legrand.us](http://www.legrand.us)

**Canada**  
905.738.9195  
[www.legrand.ca](http://www.legrand.ca)

FOLLOW US

