




radiant Collection  
**radiant® Dead Front 20A Duplex Self-Test GFCI Receptacles with SafeLock® Protection, White**  
Part No. 2087W

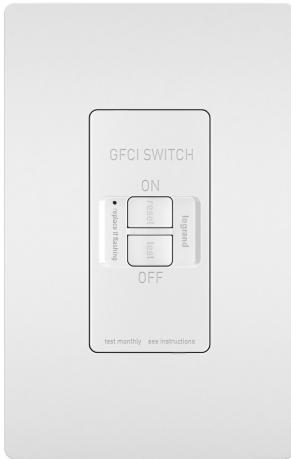

This dead front receptacle is a ground fault circuit interrupter designed for use when access to power isn't also needed. Ideal for use in spaces where ground fault protection is required around large or hard-to-move equipment, such as residential spa or hydromassage tubs and commercial kitchen appliances. The device features a convenient indicator light and accessible test/reset buttons that make trips easier to recognize and fix than with GFCI breaker alternatives. Conducts an automatic self-test every three seconds to ensure reliable protection, while also featuring the sleek, clean lines of the radiant® Collection for a sophisticated look. Made exclusively for use with screwless Wall Plates from the radiant® Collection, sold separately. Spec-Grade devices are engineered to meet federal specifications for use in commercial installations.

## Features & Benefits

Protects against shock caused by ground-fault occurrences. Unlike breaker alternatives, GFCI receptacles make it easier to fix trips with a reset button right on the device.

Equipped with proven SafeLock protection feature: if critical components are damaged and protection is lost, power to the outlet is disconnected.

Features durable, high-impact resistant thermoplastic construction.

Complete the look with a sleek, screwless radiant® Wall Plate, and coordinate with other designer switches and outlets available from the radiant® Collection.

Conducts an industry-leading automatic self-test every 3 seconds. If the device ever fails, the indicator light flashes to signal it should be replaced.

Replaces any standard receptacle with ease, in as little as 10 minutes.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

## Specifications

### General Info

Product Line	Pass & Seymour	Replaced by Part Number	
Color	White	Country Of Origin	China
Number of Receptacles	2	Outlet Type	Dead Front, GFCI, Indoor, Residential, Self-Test
Application Sector	Residential/Commercial	Standard	cULus, UL Listed, FSUL
Warranty Type	1-Year Limited Warranty	Type	Outlet

### Dimensions

---

Product Width US	1.73 in	Product Depth US	1.13 in
------------------	---------	------------------	---------

---

Product Height US	4.2 in
-------------------	--------

---

### Listing Agencies / 3rd Party Agencies

---

cULus Listed	Yes
--------------	-----

---

### Additional Information

---

Product Environmental Profile	Yes
-------------------------------	-----

---

### Technical Information

---

Interrupt Rating	4 A	Frequency Rating	60 Hz
------------------	-----	------------------	-------

---

Trip Range	5±1 mA	Connection	Back and Side Wire
------------	--------	------------	--------------------

---

Number of Gangs	1	Amperage	20 A
-----------------	---	----------	------

---

Number of Poles	Double Pole	Indoor/Outdoor	Indoor
-----------------	-------------	----------------	--------

---

Mounting Type	Box	Voltage	125.0 V
---------------	-----	---------	---------

---

Environmental Conditions	95% Humidity, UL 94 V2
--------------------------	------------------------

---