




Wiremold
8802S-FC Omnibox Series Fire Classified 2-Gang Floor Box
Part No. 8802S-FC

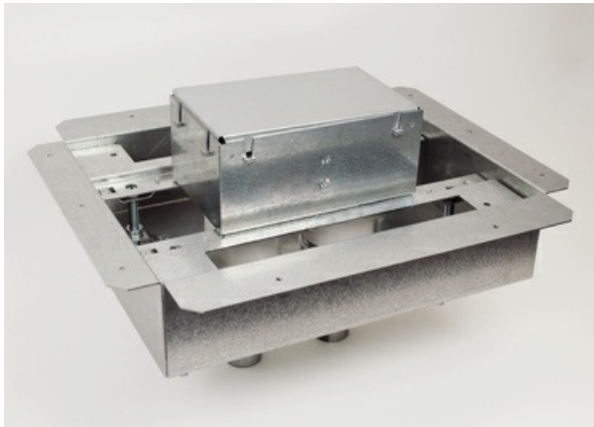

2-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 5" (127mm) maximum. Two 1 1/4" (32mm) conduit feed openings. Box Capacity - 58.5 cubic inches per gang. This floor box preserves the 2-hour fire rating of floors in which it has been installed.

Features & Benefits

2-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 5" (127mm) maximum. Two 1 1/4" (32mm) conduit feed openings. Box Capacity - 58.5 cubic inches per gang. This floor box preserves the 2-hour fire rating of floors in which it has been installed.

Specifications

General Info

Product Line	Wiremold	UPC Number	786776183153
Country Of Origin	United States	Construction	Assembled
Application Sector	Commercial	Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC.
Type	Floor Box		

Dimensions

Cubic Capacity	117 cu in
----------------	-----------

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E2961	cULus Listed	Yes
---------------------	-------	--------------	-----

Buy American Act Compliance

NAFTA	Yes
-------	-----

Additional Information

RoHS Conformant Yes

Technical Information

Cable Entry conduit Feed Channels Number of Outlets 4
