




**Wiremold**  
**8803S-FC Omnibox Series Fire Classified 3-Gang Floor Box**  
Part No. 8803S-FC

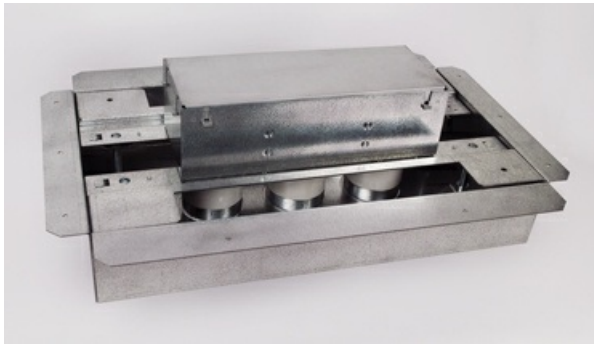

3-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 5" (127mm) maximum. Three 1 1/4" (32mm) conduit feed openings. Inside Gang Capacity - 67.5 cubic inches. Outside Gang Capacity - 54 cubic inches each gang. This floor box preserves the 2-hour fire rating of floors in which it has been installed.

## Features & Benefits

3-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 5" (127mm) maximum. Three 1 1/4" (32mm) conduit feed openings. Inside Gang Capacity - 67.5 cubic inches. Outside Gang Capacity - 54 cubic inches each gang. This floor box preserves the 2-hour fire rating of floors in which it has been installed.

## Specifications

### General Info

Product Line	Wiremold	UPC Number	786776183160
Country Of Origin	United States	Construction	Assembled
Application Sector	Commercial	Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC.
Type	Floor Box		

### Dimensions

Cubic Capacity 175.5 cu in

### Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E2961	cULus Listed	Yes
---------------------	-------	--------------	-----

### Buy American Act Compliance

NAFTA	Yes
-------	-----

### Additional Information

---

RoHS Conformant	Yes
-----------------	-----

---

### Technical Information

---

Cable Entry	conduit Feed Channels	Number of Outlets	6
-------------	-----------------------	-------------------	---

---