




**Wiremold**  
**8803S-FC12 Omnibox Series Fire Classified 3-Gang Floor Box**  
Part No. 8803S-FC12

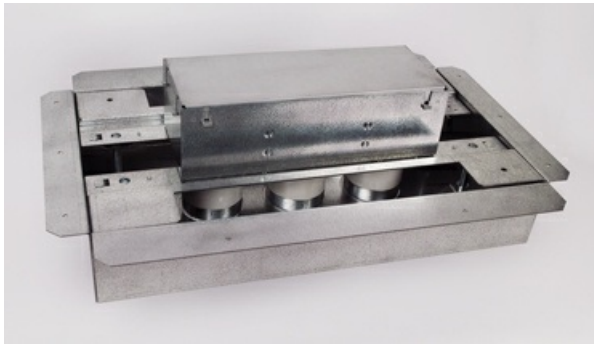

3-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 6-1/2" (165mm) maximum. One 1 1/4" (32mm) and two 2" (51mm) conduit feed openings. Inside Gang Capacity - 67.5 cubic inches. Outside Gang Capacity - 54 cubic inches each gang. This floor box preserves up to a 3- hour fire rating of floors in which it has been installed.

## Features & Benefits

3-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 6-1/2" (165mm) maximum. One 1 1/4" (32mm) and two 2" (51mm) conduit feed openings. Inside Gang Capacity - 67.5 cubic inches. Outside Gang Capacity - 54 cubic inches each gang. This floor box preserves up to a 3- hour fire rating of floors in which it has been installed.

## Specifications

### General Info

Product Line	Wiremold	UPC Number	786776184204
Country Of Origin	United States	Construction	Assembled
Number of Knockouts	1	Application Sector	Commercial
Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC.	Type	Floor Box

### Dimensions

Product Width US	11.375 in	Product Depth US	3.5 in
Product Length US	20.0 in	Cubic Capacity	54 cu in

### Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E2961	cULus Listed	Yes
---------------------	-------	--------------	-----

### Buy American Act Compliance

NAFTA	Yes
-------	-----

---

## Additional Information

---

RoHS Conformant      Yes

---

## Technical Information

---

Cable Entry      Conduits

---