




adorne Collection
adorne® Smart Tru-Universal Dimmer with Netatmo, Magnesium
 Part No. WNAL50M1

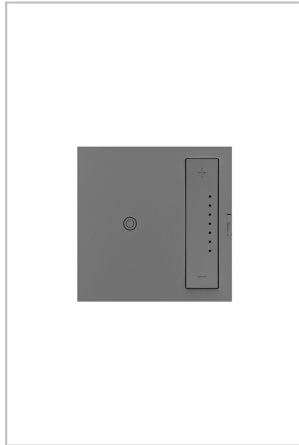

Through Tru-Universal technology, this softTap® smart dimmer switch works with virtually any 120V dimmable bulb or fixture. Pair with an adorne Wireless Smart Dimmer with Netatmo to gain easy 3-way control. Smart Lighting lets you set the exact lighting you need, from anywhere, adding safety and convenience to your home. And delivering it all with unprecedented range and reliability, adorne® with Netatmo leverages leading Netatmo technology to provide an ideal solution for larger homes with many smart products. Start with the Smart Gateway to establish a robust and dedicated mesh network, then add smart switches, smart dimmer light switches and smart outlets to build a solution that perfectly fits a home's unique space and needs. Made exclusively for use with Wall Plates from the adorne® Collection, sold separately.

Features & Benefits

Smart Gateway REQUIRED.

Controls and dims lights via smartphones and tablets using the Legrand Home + Control app. Even schedule lights to turn on/off automatically, create groups, set scenes and monitor energy usage.

Works with virtually any 120V dimmable bulb or fixture (excludes 0-10V).

Installs easily in place of an existing switch or dimmer (neutral wire required). For easy 3-way control, pair it with a Wireless Smart Dimmer with Netatmo.

Part of the adorne with Netatmo solution, which flexibly fits a home's unique needs with a variety of supported smart switches, dimmers and outlets (including wireless switches and dimmers).

Features ultra-reliable performance through a robust and dedicated mesh-network. (Established by the Smart Gateway.)

Compatible with other smart products through Amazon Alexa, Google Assistant and Apple HomeKit, as well as with home automation systems.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Complete the look with a stunning, screwless adorne® Wall Plate, not included. Available in a range of contemporary colors and finishes. Coordinate with other designer switches & outlets.

Specifications

General Info

Product Line	Pass & Seymour	Replaced by Part Number	
Color	Magnesium	Finish	Matte
Country Of Origin	China	Receptacle Type	Double

Features	Smart Lighting, With Netatmo	Switch Type	Touch
Number of Switches	1	Works With	Amazon Alexa, Apple Home Kit, Google Assistant
Application Sector	Commercial, Residential	Warranty Type	1-Year Limited Warranty
Type	Dimmer		
Dimensions			
Product Width US	1.73 in	Product Depth US	1.53 in
Product Height US	4.19 in		
Listing Agencies / 3rd Party Agencies			
cULus ListingNumber	E95219	cULus Listed	Yes
Additional Information			
RoHS Conformant	Yes		
Technical Information			
Load Rating	LED/CFL/EFL (REV): 250W, 2.1A, Incandescent, Halogen & ELV (REV): 450W, MLV (FWD) : 500VA, Incandescent, Halogen & ELV (FWD): 700W, LED/CFL/EFL (FWD): 450W, 3.8A	Compatibility	Amazon Alexa, Apple HomeKit, Google Assistant
Electrical Rating	120V 1100W (Halogen), 120V 1600VA (MLV), 120V 16A (Fluorescent), 120V 2000W (Incandescent), 120V 450W (CFL), 120V 450W (LED), 120V 5A (Fan Control), 120V 700W (ELV), 120V 8A (EFL)	Number of Wires	4
Bulb Compatibility	CFL, Fluorescent, Halogen, HID, Incandescent, LED, Universal, Xenon	Number of Poles	3-Way, Multi-Location, Single Pole

Wattage

700 W

Supply Voltage

120 VAC

Voltage

120.0 V

Connection Type

Wired

Load Type

Incandescent, Halogen & ELV
