




Pass and Seymour
Smart Tru-Universal Plug-in Dimmer with Wi-Fi
Part No. WWP20CCV2

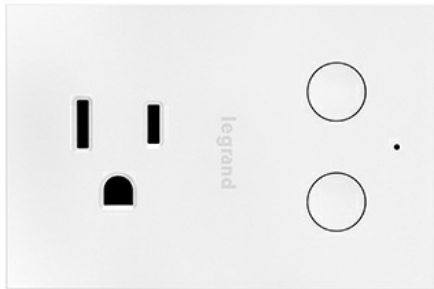

Take comfort in the convenience of controlling your lights from any smart device, from anywhere. The Smart Plug-In Dimmer, Wi-Fi offers precise light level control, and the ability to set scenes and schedules, all from any smart device. Or, just ask Alexa or Google to turn the lights on for you. Combining classic design and advanced functionality with simple connection among existing smart home solutions using your home's wireless network, Smart Lighting from the radiant® Collection sets the exact lighting you want – when and where you need it. Tru-Universal Dimmers work with virtually any 120V dimmable bulb or fixture, adjusting to the exact light level you want, without the flicker.

Features & Benefits

- Control lights from smart phones and tablets with the Smart Lights app. Even schedule lights to turn on/off automatically, create groups or set scenes.
- Provides dimmable control of table and floor lamps using any 120V dimmable bulb.
- Just ask Amazon Alexa or Google Assistant to turn on the lights.
- Set the exact lighting level you need.
- Works with a home's existing secure Wi-Fi network (WPA2). Also includes out-of-the-box connectivity with other smart devices through OCF certification.
- Installs easily, no wiring required. Simply plug in to an existing 120V electrical outlet.
- Know your home is secure, even when you're away.

Specifications

General Info

Product Line	Pass & Seymour	Color	White
Finish	Gloss	UPC Number	785007235869
Country Of Origin	China	Features	Plug-In
Switch Type	Button, Push	Works With	Amazon Alexa, Google Assistant
Application Sector	Residential	Warranty Type	Limited Lifetime Warranty

Dimensions

Product Width US	3.0 in	Product Depth US	1.31 in
------------------	--------	------------------	---------

Product Height US	2.0 in
-------------------	--------

Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

Technical Information

Dimming Compatibility	Forward or Reverse Selectable Phase	Frequency Rating	60 Hz
Number of Poles	Single Pole	Indoor/Outdoor	Indoor
Mounting Type	Plug-in	Wire Connection Type	Plug-In
Voltage	120 VAC	Load Type	CFL, Halogen, Incandescent, LED